

KEY CONTACTS:

Bill Hathaway

Government Sales Manager
763.528.7081 Direct
866.829.5090 Toll Free
bill.hathaway@cummins.com

Ray Makepeace

Government Sales Manager
763.574.5766 Direct
866.829.5090 Toll Free
ray.l.makepeace@cummins.com

Mike Schmitt

Government Sales Manager
763.528.7034 Direct
866.829.5090 Toll Free
mike.p.schmitt@cummins.com

Bob Schaefer

Director, Global Strategic Accounts
763.574.5595 Direct
866.829.5090 Toll Free
robert.schaefer@cummins.com

GSA contract #GS-07F-9004D



Schedule
Contract



www.cumminspower.com/GSA
www.cumminsonan.com/GSA
www.gsaadvantage.gov



Cummins Power Generation
1400 73rd Ave NE
Minneapolis, MN 55432

www.cumminspower.com/GSA
www.cumminsonan.com/GSA
www.gsaadvantage.gov

©2011 Cummins Power Generation Inc. All rights reserved. Cummins Power Generation, Cummins, Onan, Cummins Onan and the "C" logo are registered trademarks of Cummins Inc. F-1741 (4/11)



Power to serve



Government Sales

GSA contract #GS-07F-9004D


Cummins Power Generation Inc. is proud to serve those who serve

Our legacy of partnering with the U.S. government dates from World War II, when Allied forces relied on Onan-branded power generation equipment. Today, our government sales team continues to work on your behalf to deliver optimized power solutions in the field.

The Cummins Power Generation/ Cummins Onan advantage:

- World-class products
- Technology leadership
- 24/7 worldwide service
- Product training program
- Compliant with Buy America regulations

GSA contract #GS-07F-9004D

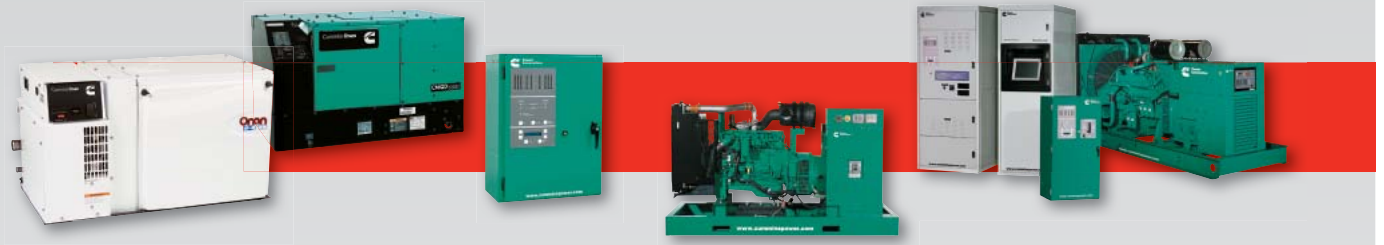

60 Hz Diesel Generator Set

Standby 3-Phase Rating

kW / kVA	MODEL
10 / 12.5	DSKAA
15 / 18.8	DSKAB
20 / 25	DSKBA
25 / 31	DSKCA
35 / 44	DSFAA
40 / 50	DSFAB
50 / 63	DSFAC
60 / 75	DSFAD
80 / 100	DSFAE
100 / 125	DSGAA
125 / 156	DSGAB
150 / 188	DSGAC
175 / 219	DSHAB
200 / 250	DSHAC
230 / 288	DSHAD
250 / 313	DQDAA
275 / 344	DQHAA
300 / 375	DQHAB
350 / 438	DFEG
400 / 500	DFEH
450 / 563	DFEJ
500 / 625	DFEK
600 / 750	DQCA
750 / 938	DQCB
750 / 938	DQFAA
800 / 1000	DQCC
800 / 1000	DQFAB
900 / 1125	DQFAC
1000 / 1250	DQFAD
1250 / 1563	DQGAA
1500 / 1875	DQGAB
1750 / 2188	DQKAA
2000 / 2500	DQKAB
2500 / 3125	DQLE

60 Hz Natural Gas or Propane Generator Set

Standby 3-Phase Rating

kW / kVA	MODEL
20 / 25	GGMA
25 / 31	GGMB
29 / 36	GGMC
35 / 44	GGPA
40 / 50	GGPB
45 / 56	GGPC
60 / 75	GGHE
70 / 88	GGHF
85 / 106	GGHG
100 / 125	GGHH
125 / 156	GGLA
150 / 188	GGLB

Transfer Switch

MODEL	AMPERE RATING
OTIII Manual	40 – 1000
OTEC Automatic	40 – 1200
OTPC Automatic	40 – 4000
CHPC Closed Transition	125 – 800
OHPC Open Transition	120 – 800
BTPC Bypass	150 – 4000
OTEC SE Service Entrance	40 – 1000
OTPC SE Service Entrance	40 – 1000

For a complete listing of products, please go to www.gsaadvantage.gov or contact one of our government sales managers.

