


POWER YOUR ADVENTURES.

NEW

Onan P2500i

2500 Watt Digital Inverter Gasoline Portable Generator
2200 Running Watts | 2500 Peak Watts

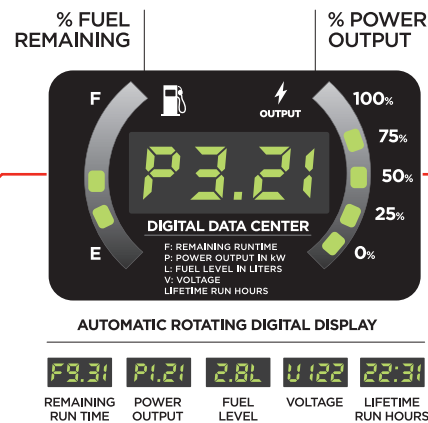

LED DISPLAY

Precise readings to keep you in the know.

- **PARALLEL CAPABLE**

Capable of paralleling with another P2500 inverter generator.

- **QUIET & DURABLE**

Double-insulated

- **LIGHTWEIGHT**

Easy to carry

- **KEEPS YOU CONNECTED**

Low THD for clean power—perfect for sensitive electronics

- **FUEL EFFICIENT**

1 gallon fuel tank that runs 10 hrs at 25% load



Onan P2500i

Inverter Generator Features and Specifications

- Built-in carry handle for easy transportation
- Parallel capable with another P2500 inverter generator (cable sold separately)
- Two 5V USB ports for charging sensitive electronics such as phones or tablets
- Rubber outlet dust covers
- Dependable 3.4 HP 98cc OHV 4-Stroke engine
- Rubber mat on top for storing electronic devices such as phones while charging
- 3-Year Warranty

Part Number	A058U944
Gasoline Peak Watts	2500
Gasoline Running Watts	2200
Peak Amps at 120V	20.8 amps
Running Amps at 120V	18.3 amps
AC Voltage	120 Volts
DC Voltage	5 Volts
AC Frequency	60 Hz
Parallel Capable	Yes
Engine Horse Power (HP)	3.4 HP
Total Harmonic Distortion (THD)	<3%
Automatic Voltage Regulator (AVR)	Yes
Starting System	Recoil
Battery	No
Engine Displacement	98cc
Engine Brand	Ducar
Engine Type	OHV 4 Stroke
Engine Speed	Variable
Engine RPM	Max 5500
Available in True Timber Camo	Yes
Operational Volume	As low as 52 dBA
Spark Plug (included)	Torch E6RTC
Carburetor Kit Required to Operate at Altitude	Yes, above 2000ft
Economy Mode Switch	Yes
Built-in Inverter	Yes
Engine Lubrication	Splash
Recommended Oil	SAE 10W30
Oil Bottle Size (included)	.37 qt. (11.8 oz.)
Oil Capacity (Quarts/Ounces)	.37 qt. (11.8 oz.)
Low Oil Shutdown	Automatic
Fuel Type	Unleaded Gasoline, 10% Ethanol or less
Fuel Shut Off	Manual
Fuel Tank Material	Steel
Fuel Tank Capacity (Gallons/Liters)	1 gal. (3.8 L)
Run Time at %25 Load (hrs.)	10 hrs.
Run Time at %50 Load (hrs.)	8 hrs.
Gasoline Fuel Gauge	Yes

Choke type	Manual
Choke Location	Control Panel
AC Outlets	(1) Duplex 120V 20A (5-20R)
DC Outlets	(2) 5V USB ports (1) 12V 8A outlet
Ground	Floating Neutral
Covered Outlets	Yes
Transfer Switch Ready	No
GFCI Outlets	No
LED Data Center	Yes
Overload Protection (circuit breaker)	Yes
Handle Style	Single, molded in case
Wheel Kit	No
Emissions	EPA, CARB
Canada CSA Compliant	Yes
Spark Arrestor	Yes
Residential Warranty	3 Years
Commercial Warranty	1 Year
Assembled Length in. (mm)	19.75 in. (501.65 mm)
Assembled Width in. (mm)	10.5 in. (266.7 mm)
Assembled Height in. (mm)	18.25 in. (463.55 mm)
Carton Length in. (mm)	21.5 in. (546 mm)
Carton Width in. (mm)	12.75 in. (323.85 mm)
Carton Height in. (mm)	18.75 in. (490 mm)
Dry Unit Weight lb. (kg)	48 lb. (21 kg)
Shipping Weight lb. (kg)	56 lb. (24 kg)

cummins.com

 [Instagram.com/Cummins](https://www.instagram.com/Cummins)

 [Twitter.com/Cummins](https://twitter.com/Cummins)

 [Facebook.com/Cummins](https://www.facebook.com/Cummins)

 [YouTube.com/Cummins](https://www.youtube.com/Cummins)

